



One Source . Infinite Solutions
Your complete lab resource

**LABORATORY ESSENTIAL
PROMOTION 2021**

Best Deals

Fisherbrand Cell Cultureware

Fisherbrand Multi-Well Tissue Culture Plates

- Vented lids with condensation rings
- Notched plates and lids for easy orientation
- Alphanumerically labelled well
- Individually packaged (paper/plastic blister packaging)

Fisherbrand 4 well TC multidish, 100/case
Part No: LSV#FB012926

Fisherbrand 6 well TC multidish, 100/case
Part No: LSV#FB012927

Fisherbrand 12 well TC multidish, 100/case
Part No: LSV#FB012928

Fisherbrand 24 well TC multidish, 100/case
Part No: LSV#FB012929

Fisherbrand 48 well TC multidish, 100/case
Part No: LSV#FB012930

Fisherbrand 96F well TC multidish, 100/case
Part No: LSV#FB012931

Fisherbrand 96U well TC multidish, 100/case
Part No: LSV#FB012932



Fisherbrand Tissue Culture Flasks

- Conform with USP Class VI and ISO 10993-5 standards
- Non-pyrogenic and non-cytotoxic
- DNase and RNase free
- BSE and TSE free
- Lot numbers appear on case labels, inner packaging, and individual pieces

25cm² Flask, TC treated, vented cap, 200/case
Part No: LSV#FB012935

25cm² Flask, TC treated, plug seal cap, 200/case
Part No: LSV#FB012936

75cm² Flask, TC treated, vented cap, 100/case
Part No: LSV#FB012937

75cm² Flask, TC treated, plug seal cap, 100/case
Part No: LSV#FB012938

182cm² Flask, TC treated, vented cap, 40/case
Part No: LSV#FB012939

182cm² Flask, TC treated, plug seal cap, 40/case
Part No: LSV#FB012940



Fisherbrand Tissue Culture Dishes

- Stackable lids with ventilation ribs
- Gripping ring included (except for 35mm and 150mm sizes)
- Resealable, self-standing packaging

35mm TC dish, 960/case
Part No: LSV#FB012920

60mm TC dish, with gripping ring 600/case
Part No: LSV#FB012921

90mm TC dish, 500/case
Part No: LSV#FB012923

100mm TC dish, with gripping ring 300/case
Part No: LSV#FB012924

150mm TC dish, 120/case
Part No: LSV#FB012925

 


Best Deals

LabServ Cell Cultureware

LabServ Tissue Culture Well Plates

- Individually packed in peel-to-open wrap promises sterility
- Each lot is tested for sterility and endotoxin level
- Clear graduations for accurate volume measurement



6 Well Cell Culture Plate, Flat, TC, Sterile 1/pk, 50/cs
Part No: LSV#310109005

12 Well Cell Culture Plate, Flat, TC, Sterile 1/pk, 50/cs
Part No: LSV#310109006

24 Well Cell Culture Plate, Flat, TC, Sterile 1/pk, 50/cs
Part No: LSV#310109007

96 Well Cell Culture Plate, Flat, TC, Sterile 1/pk, 100/cs
Part No: LSV#310109008

LabServ Tissue Culture Dishes

- Surface-treated and non-pyrogenic & DNase- and RNase-free
- Easily stackable for storage and handling
- Sterilized by E-beam
- High clarity polystyrene for distortion-free observation

35mm Cell Culture Dish, TC, Sterile 10/pk, 500/cs, resealable. Part No: LSV#310109009

60mm Cell Culture Dish, TC, Sterile 10/bag, 500/cs, resealable. Part No: LSV#310109010

100mm Cell Culture Dish, TC, Sterile 10/bag, 300/cs, resealable. Part No: LSV#310109011

150mm Cell Culture Dish, TC, Sterile 5/pk, 100/cs. Part No: LSV#310109012



Conical Tubes

Blue Flat Top Cap, Conical Bottom, Sterilized

- Leak-proof screw cap design
- Easy-to-read black graduations with accuracy of 2%
- Able to withstand up to 12,500 xg
- Autoclavable at 121°C and freezable to -80°C
- Manufactured in ISO 5 Clean Room Environment

LabServ 15ml, 25/Rack, 2 racks/pkg, 500/case
Part No: LSV#14955159B

LabServ 50ml, 25/Rack, 500/case
Part No: LSV#14955161B

LabServ 15ml, 50/Rack, 500/case
Part No: LSV#14955160B

LabServ 50ml, 25/Rack, 500/case
Part No: LSV#14955162B



LabServ Tissue Culture Flasks

- Available in both vent caps and plug seal caps
- Vent caps with 0.22µm hydrophobic filters to ensure gas exchange without contamination
- Surface-treated and non-pyrogenic, DNase/RNase-free
- Clear lot number for batch traceability
- Frosted writing and clear graduation
- Sterilized by E-beam



25cm² Cell Culture Flask, Plug Seal Cap, TC, Sterile 10/pk, 200/cs
Part No: LSV#310109013

25cm² Cell Culture Flask, Vent Cap, TC, Sterile 10/pk, 200/cs
Part No: LSV#310109014

75cm² Cell Culture Flask, Plug Seal Cap, TC, Sterile 5/pk, 100/cs
Part No: LSV#310109015

75cm² Cell Culture Flask, Vent Cap, TC, Sterile 5/pk, 100/cs
Part No: LSV#310109016

175cm² Cell Culture Flask, Plug Seal Cap, TC, Sterile 5/pk, 40/cs
Part No: LSV#310109017

175cm² Cell Culture Flask, Vent Cap, TC, Sterile 5/pk, 40/cs
Part No: LSV#310109018

Serological Pipette

Individually packed, Sterilized, Non-Pyrogenic | **NEW** filter plugs with improved protection against carryover contamination

- Individually packed in peel-to-open wrap promises sterility
- Each pipette lot is tested for sterility, accuracy and endotoxin level
- Factory calibrated ISO 8655
- Non-pyrogenic, DNase- and RNase-free


LabServ 1ml Serological Pipet, 100pkg, 1000/case
Part No: LSV#14955153

LabServ 2ml Serological Pipet, 50pkg, 500/case
Part No: LSV#14955154

LabServ 5ml Serological Pipet, 50pkg, 200/case
Part No: LSV#14955155

LabServ 10ml Serological Pipet, 50pkg, 200/case
Part No: LSV#14955156

LabServ 25ml Serological Pipet, 50pkg, 200/case
Part No: LSV#14955157

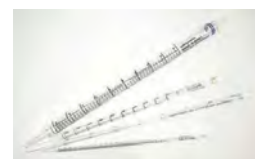

Best Deals

Fisherbrand™ Microcentrifuge Tubes with Locking Snap Cap

- DNase/RNase and pyrogen free
- Autoclavable and able to withstand temperatures to -86°C
- Able to reach up to 26,000 xg
- Non-sterile
- Natural Color

Fisherbrand 1.5ml MCT, Natural, NS, RNA-free, 500PK

Part No: LSV#14-666-319PK



LabServ Petri Dish

- Manufactured from non-cytotoxic virgin polystyrene
- Good optical clarity for easy colony identification
- Rigidity to resist excessive deformation during agar preparation
- Consistent dimensions with smooth edges
- Sterilized by gamma irradiation
- Stackable & anti-slip
- Triple vent provides adequate gas exchange



90mm Petri Dish Gamma Irradiation, 500/Bx
Part No: LSP#LAB-02-FS

Fisherbrand Mini Centrifuge

- Small footprint and quiet operation
- Palm-shaped lid, suitable for left or right handed users. Allows quick extraction of tubes
- Snapspin™ rotors are tool-free for a fast and easy exchange
- Weighted rubberized base eliminates potential movement and further dampers vibration and noise
- Package includes: Mini-centrifuge, 6 place 1.5/2.0ml tube rotor, 16 place 0.2ml tube rotor (singles or 2 x 8 strip), 6 tube adapters 0.2ml, 6 tube adapters 0.5ml, 4 o-rings, storage case for rotors and adapters, tube rack, low voltage & double insulated power adapter with 4 interchangeable plugs



Fisher Scientific Std Mini-Centrifuge, 230V/50Hz
Part No: FBA#12-006-901

LabServ Vortex Mixer

- Variable speed rotary dial provides pre-set speed control (1000, 2000, 3000 rpm) during vortex mixing
- Stable elastomeric device feet, provide vibration dampening and prevent movement during operation
- Holding slots for no less than seven different sizes of tubes and a standard assay plate
- Innovative head can be removed for cleaning
- High impact ABS body shell
- US Design Patent No. D787,085



LabServ Multi Purpose Vortex Mixer (HS120490)
Part No: FBA#12-006-800

Fisherbrand Homogenizer

- Homogenize up to 24 samples in seconds
- Broad performance range 1 to 6 m/s
- Sample volumes ranging from 25uL to 2mL
- Maintenance free
- Programmable time, dwells, multiple cycles
- Built-in safety sensors and temperature sensor
- Able to up-scale to 15 or 50ml tube by changing the tube adaptors
- Optimal for cryogenic unit for heat-sensitive sample processing



FB Bead Mill 24 with FOC 2 x Bead Kit

- Fisherbrand Bead Mill 24
- Fisherbrand 2ml tube with 2.8mm ceramic beads (RNase/DNase free)

Part No: FBO#15515799 & FBO#15565799

Fisherbrand 850 Homogenizer Package

- Variable speed setting from 5,000 to 25,000 rpm
- Processing capacity from 200uL to 5L
- Digital speed control with soft start and built-in timer
- Ideal for remote applications in fume hoods or biosafety cabinets



Part No: FBO#15515819

Fisherbrand Overhead Stirrer

Compact overhead stirrer, ideal for continuous, general purpose mixing.
Easily fits into fume hoods or enclosed workstations

- Delivers accurate, repeatable results for volumes up to 25L and 15,000cps
- Four-digit speed display shows speed accurate to ± 1 rpm
- Last speed setting is stored in memory before unit is powered off
- Brushless, maintenance-free DC motor produces consistent mixing at all speeds and provides automatic overload protection



Fisherbrand Compact Digital Overhead Stirrer 220V
Part No: FBF#FSR2220U1

Bundle with:

Stand Compact - Base with 610 x 16 mm stand rod
Part No: CFM#A210

Clamp - accepts 12.5 mm support rod
Part No: CFM#A120

Propeller 64 mm dia
Part No: CFM#A166

Best Deals

Fisherbrand Sonicator

High power, programmable system ideal for nanotechnology, cell disruption and homogenization applications

- Processes 0.2 to 1000mL
- Programmable from 1 second to 10 hours
- A variety of accessories are available including probes for individual samples and a Cup Horn for indirect sonication

Main Unit | 500 WATT Sonic Dismembrator
Part No: FQS#FB505220



Option 1 | Sound enclosure with converter clamp
Part No: FQS#FB432B2

Option 2 | Stand with Clamp-MDL 505 OR 705
Part No: FQS#FB459

Fisherbrand Ultrasonic Bath

Designed with state of the art microprocessor controlled ultrasonic cleaning and sweep technology. Fisherbrand™ S-Series Ultrasonic Cleaners offer a comprehensive range of analogue ultrasonic baths covering the requirements for laboratory research, sonochemistry and degassing applications.

- Long lifespan from cavitation resistant stainless steel tanks
- LED display showing set and remaining time and pre-set and actual temperature
- Newly developed cover reduces noise and accelerates the heating up process
- Easy draining of cleaning liquid through the drain duct via a dial on the side



Ultrasonic Bath, S 60 H
Part No: FBE#FB15055

Bundle with:

Holder baskets s/s For use wt FB15054/FB15055
Part No: FBE#100 4243

Covers plastic for use wt FB15054/FB15055
Part No: FBE#100 3282

Fisherbrand™ Autoclavable Bottle Top Dispenser

- Provides smooth, effortless dispensing with adjustable delivery nozzle
- Fully autoclavable and high chemical compatibility
- Design with PTFE piston for smooth movement

FB Bottle Top Dispenser 0.25 to 2.5ml
Part No: FBD#1361510

FB Bottle Top Dispenser 0.5 to 5.0ml
Part No: FBD#1361511

FB Bottle Top Dispenser 1.0 to 10.0ml
Part No: FBD#1361512

- Factory calibrated ISO 8655
- Each bottle top dispenser includes one 28mm, 32mm, 36mm, 40mm, 45mm bottle neck adaptor

FB Bottle Top Dispenser 2.5 to 30.0ml
Part No: FBD#1361513

FB Bottle Top Dispenser 5.0 to 60.0ml
Part No: FBD#1361514

FB Bottle Top Dispenser 10.0 to 100.0ml
Part No: FBD#1361515



Best Deals

Fisherbrand Isotemp Hotplate Stirrer

Fisherbrand™ Isotemp™ hotplate stirrers are designed to provide precise stirring control, exceptional safety and temperature performance for your routine protocols

- HOT TOP warning system designed to protect from accidental burns with prominent display when heating surface is above 50°C (122°F)
- Automatic over-temperature protection
- Optional temperature probe and splash guard protection shield
- Stir bar is included with stirrer and stirring hotplate models



Isotemp 10"x10" Hotplate Stirrer 230V 50/60Hz
Part No: FMM#SP88850206

Isotemp 7"x7" Hotplate Stirrer 230V 50/60Hz
Part No: FMM#SP88857206

Fisherbrand Balance

- Standard RS232 connectivity for easy data transfer
- Durably constructed, and features a stainless steel pan to withstand day-to-day use
- Two adjustable feet that allow user to level the balance
- A large, bright backlit display allows for easy viewing of results



220g capacity with 0.1mg readability, 4 d.p., InCal
Part No: FBS#15927500

4200g capacity with 0.01mg readability, 2 d.p., InCal
Part No: FBS#15927510

Fisherbrand pH Meter

Provide intuitive, simple operation and high accuracy measurements in a compact, affordable meter

- Graphic backlit display with date and time, stability indicator and alarms
- pH slope and offset display
- Automatic or manual temperature compensation, displayed in °C or °F
- Password protection of calibration and setup modes
- RS232 and USB interfaces



ACCUMET AB150 PH KIT
Part No: FSP#13-636-AB150

ACCUMET AB200 PH/CON KIT
Part No: FSP#13-636-AB200

ACCUMET AB250 PH/ISE KIT
Part No: FSP#13-636-AB250

Fisherbrand Isotemp Water Bath

Fisherbrand™ Isotemp™ general purpose deluxe water baths provide powerful technology in a compact design

- Smaller footprint, compared to previous models
- Advanced temperature controller is designed for extended functionality
- Simple to operate and monitor with icon-based graphical display
- Enhanced hinge design supports open lid configuration and easy lid removal
- Low-fluid protection prevents bath damage and overheating



Isotemp 5L General Purpose Water Bath
Part No: FTN#FSGPD05

Isotemp 10L General Purpose Water Bath
Part No: FTN#FSGPD10

Isotemp 20L General Purpose Water Bath
Part No: FTN#FSGPD20

Isotemp 28L General Purpose Water Bath
Part No: FTN#FSGPD28

Fisherbrand Media Bottle

Fisherbrand™ Reusable Glass Media Bottles with Cap feature a convenient wide opening, enhanced graduations and a polypropylene pour ring. Feature clear (natural), drip-free, replaceable polypropylene pour ring.

Fisherbrand Reusable Glass Media Bottle with Cap, 100ml
Part No: FKI#FB800-100

Fisherbrand Reusable Glass Media Bottle with Cap, 250ml
Part No: FKI#FB800-250

Fisherbrand Reusable Glass Media Bottle with Cap, 500ml
Part No: FKI#FB800-500

Fisherbrand Reusable Glass Media Bottle with Cap, 1000ml
Part No: FKI#FB800-1000

Fisherbrand Reusable Glass Media Bottle with Cap, 2000ml
Part No: FKI#FB800-2000



Best Deals

Fisherbrand Traceable® Series

Timer/Thermometer

We offer a complete range of test and measurement instruments that are individually serialized, calibrated and certified Traceable to NIST

Fisherbrand Temperature/Clock/Humidity Monitor
Part No: CTL#06-662-4



Thermometer Digital Waterproof,
Traceable Fisher Scientific
Part No: CTL#14-648-44



Timer Alarm, Big Digit, 4-Channel, Traceable (5004)
Part No: CTL#14-649-17



Fisherbrand Traceable Min/Max Thermometers

- Records minimum and maximum readings
- Obtain accurate results for a variety of environment and laboratory monitoring conditions
- Visual and audible alarms event
- Programmable high or low alarm settings

Fisherbrand Min/Max Thermometer
(Accuracy of $\pm 1^{\circ}\text{C}$; -50 to 70°C)
Part No: CTL#06-664-11



Fisherbrand Min/Max Thermometer
(Accuracy of $\pm 0.5^{\circ}\text{C}$; -50 to 70°C)
Part No: CTL#06-664-23



Fisherbrand™ Traceable® Excursion-Trac™

- Digitally track your temperature readings 24/7
- Maintain the most recent 525,600 temperature observations (rolling memory)
- Transfer recorded data in CSV format via USB drive - no software required
- Audible/visual alarm when parameters have been breached
- Meets CDC/VFC requirements

Temperature Datalogger for LRF

Datalogging Thermometers (Bottle probe; -50 to 70°C)
Part No: CTL#15-081-123

Datalogging Thermometers (Bullet probe; -50 to 70°C)
Part No: CTL#15-081-125

Datalogging Thermometers (Stainless steel probe; -50 to 70°C)
Part No: CTL#15-081-128

Datalogging Thermometers
(Vaccine bottle probe; -50 to 70°C)
Part No: CTL#15-079-656

Datalogging Thermometers
(Plastic bottle probe; -50 to 70°C)
Part No: CTL#15-079-660



Temperature Datalogger for ULT

Datalogging Thermometers (Platinum RTD probe; -90 to 105°C)
Part No: CTL#15-079-624

Temperature Datalogger for LN2 Tank


Traceable® LN2 Thermometer Datalogging Thermometers (Platinum RTD probe; -200 to 105°C)
Part No: CTL#15-079-669



Best Deals

Fisherbrand™ Traceable® Memory-Loc™

- Digitally track your temperature readings 24/7
- Can store more than 1 million data points and no data overwriting
- Transfer recorded data in CSV format via USB drive - no software required
- Audible/visual alarm when parameters have been breached
- Comply to 21 CFR 11 requirement

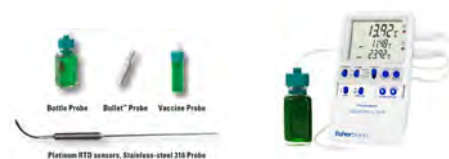

Temperature Datalogger for LRF

Fisherbrand™ Traceable Memory-Loc™ Datalogging Thermometers (Bottle probe; -50 to 70°C) Part No: CTL#15-081-130

Fisherbrand™ Traceable Memory-Loc™ Datalogging Thermometers (Stainless steel probe; -50 to 70°C) Part No: CTL#15-081-135

Fisherbrand™ Traceable Memory-Loc™ Datalogging Thermometers (Bullet probe; -50 to 70°C) Part No: CTL#15-081-132

Fisherbrand™ Traceable Memory-Loc™ Datalogging Thermometers (Vaccine bottle probe; -50 to 70°C) Part No: CTL#15-081-632

Temperature Datalogger for ULT

Fisherbrand™ Traceable Memory-Loc™ Datalogging Thermometers (Platinum RTD sensor; -200 to 105°C) Part No: CTL#15-081-622



Temperature Datalogger for LN2 Tank

Fisherbrand™ Traceable Memory-Loc™ Datalogging Thermometers (Platinum RTD sensor; -200 to 105°C) Part No: CTL#15-079-671

Fisherbrand Traceable® Series

Fisherbrand™ Traceable® Logger-Trac™

For monitoring material during storage, handling and transportation

Temperature Datalogger for Transportation

- Display cumulative Alarm Duration from user selected MIN/MAX values
- Integrates with MaxiThermal Software for complete data analysis
- Reusable/Re-programmable
- Storage Capacity: 7,680 readings
- IP66 Waterproof Rating
- Pre-programmed with alarm values of 2°C (low) and 8°C (high) and a recording interval to allow for 30 days of recording (readings are logged every 5 minutes, 33 seconds)

Temperature Datalogger (-35 to 50°C)
Part No: CTL#15-081-144



Bundle with:
Logger-Trac cradle and USB cable
Part No: CTL#15-081-148



MaxiThermal Software
Part No: CTL#15-081-150



Datalogging Hygrometers

Used to read temperature, relative humidity and time. It is great for hoods, storerooms, cleanrooms and other environments that need to be monitored

- Excursion-Trac: Rolling memory structure, maintains 525,504 observations
- Memory-Loc: Fixed memory structure, maintains 688,086 observations; 21 CFR Part 11 compliance
- Visual/audible Smart-Alarm™ and stores up to 30 unique alarm events
- Hassle-free retrieval of data via USB data transfer
- Status indicators - Low battery, memory full, USB data transfer and active alarm state

Fisherbrand™ Excursion-Trac™

Datalogging Hygrometers (Temp/RH)

Datalogging Traceable™ Hygrometer
Part No: CTL#15-079-665



Fisherbrand™ Memory-Loc™

Datalogging Hygrometers (Temp/RH)

Datalogging Traceable™ Hygrometer
Part No: CTL#15-079-667

Best Deals

Datalogging Barometers

Simultaneously monitor barometric pressure, temperature and humidity

- Excursion-Trac: Rolling memory structure, maintains 525,600 observations
- Memory-Loc: Fixed memory structure, maintains 819,150 observations; 21 CFR Part 11 compliance
- Visual/audible Smart-Alarm™ and stores up to 30 unique alarm events
- Hassle-free retrieval of data via USB data transfer
- Status indicators - Low battery, memory full, USB data transfer and active alarm state
- Altitude Compensation from -100 to 2500 meters

Fisherbrand™ Excursion-Trac™

Datalogging Barometers

Datalogging Traceable™ Barometer
Part No: CTL#15-079-666

Fisherbrand™ Memory-Loc™

Datalogging Barometers

Datalogging Traceable™ Barometer
Part No: CTL#15-079-668



Terms & Conditions:

- Promotion is valid until **31st December 2021**
- All pre-orders must be made with the promotional period
- Lab Essentials Promotion is not applicable for on-going promotions
- While stock last



For more information, contact Fisher Scientific

Malaysia:

For customer service, call +603 5122 8888

Email, enquiry.my@thermofisher.com

fishersci.com.my | myfisherstore.com/malaysia

 **fisher scientific**
part of **Thermo Fisher Scientific**

For Research Use Only. Not for use in diagnostic procedures. © 2021 Thermo Fisher Scientific Inc. All rights reserved.
All trademarks are the property of Thermo Fisher Scientific and its subsidiaries unless otherwise specified.

 **fisher scientific**